

MAXXFAST Through bolt
anchor Steel Zinc plated
M10X115



Article number	30554.100.115
Brand	-
UBB	500619774630
UNSPSC	31162101
EAN	8715494137928
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M10
Length	115 mm
Material	Steel
Approval	ETA Option 1
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	PROMAXX

Info	Code = Letter code markingdo = Nominal diameter of drill bitdf = Diameter of clearance hole in the fixtureh1 = Depth of drilled hole to deepest pointhnom = Minimum hole depthhef = Effective anchorage depthtfix(max) = Grip ranges = Width across flatsring ø = Washer diameterScr,N = Spacing characteristicCcr,N = Edge distance characteristicSmin. = Minimal spacingCmin. = Minimal edge
------	--


Standards

distanceNrec =
Recommended
load in kNTinst =
Tightening torque
in NmThe allowable
load (Nrec) is valid
for one single
anchor, at non-
cracked concrete
(pressure zone)
with concrete class
C20/25, incl. partial
safety factor $\gamma_f = 1,4$
and if the Scr,N and
Ccr,N are taken in
to account.When
reduction on spacing
and edge distance
take place a re-
calculation of forces
should be carried
out by making use of
the technical guide,
they are available
on request.Final
calculations should
comply with the
complete European
Technical Approval
(ETA), this approval
is also available on
request.

Technical Specification

Ccr, N	90
Cmin.	90
d-D	M10
df	12
do	10
h (nom.)	68
h1	75
hef	60
L (mm)	115
Nrec	4.76
Ring ø	20
s	17
Scr, N	150
Smin.	90

Technical Drawing

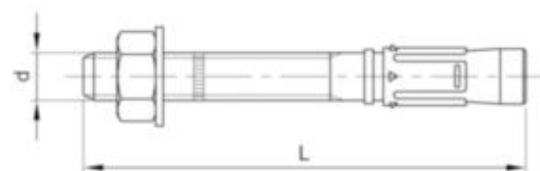

tfix(max.)	35
------------	----

Tinst	40
-------	----

FABORY