


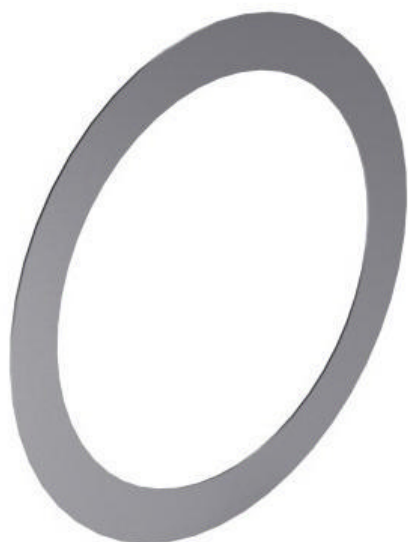

Shim ring thickness h=0,25mm DIN 988 Steel 2 K 50 Plain h=0,25mm 5X10MM

Article number	38602.050.010
----------------	---------------

Brand	-
-------	---

UBB	500645302109
-----	--------------

UNSPSC	31163301
--------	----------

EAN	8717077086951
-----	---------------

PKG. of 100	Full Box Only
-------------	---------------

Technical Parameters

Diameter	5 mm
----------	------

Material	Steel
----------	-------

Material technical	2 K 50
--------------------	--------

Outer diameter	10
----------------	----

Surface treatment	Plain
-------------------	-------

Info	h=0,25MM
------	----------

Standards

DIN	988
-----	-----

Technical Specification

d1	5
----	---

d1 (max.)	5.15
-----------	------

d1 (min.)	5.03
-----------	------

d2	10
----	----

d2 (max.)	9.96
-----------	------

d2 (min.)	9.81
-----------	------

D (mm)	5
--------	---

Thickness	0.25
-----------	------

Technical Drawing

