



Grooved pin, full length taper grooved DIN 1471 Free-cutting steel 1,5X4MM

Article number	39710.015.004
Brand	-
UBB	950359124431
UNSPSC	31163215
EAN	8715492823878
PKG. of 200	Full Box Only

Technical Parameters

Diameter	1.5 mm
Length	4 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

NEN	≈2602
ISO	≈8744
DIN	1471

Technical Specification

c ≈	0.2
d1	1.5
d2 ≈	1.6
D (mm)	1.5
L (mm)	4

Technical Drawing

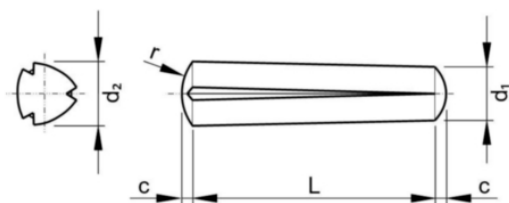

$r \approx$ 1.5

Tolerance h9

V 1.6