



Grooved pin, full length taper grooved DIN 1471 Free-cutting steel 2,5X10MM

Article number	39710.025.010
Brand	-
UBB	950359126337
UNSPSC	31163215
EAN	8715492824066
PKG. of 200	Full Box Only

Technical Parameters

Diameter	2.5 mm
Length	10 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1471
ISO	≈8744
NEN	≈2602

Technical Specification

c ≈	0.3
d1	2.5
d2 ≈	2.65
D (mm)	2.5
L (mm)	10

Technical Drawing

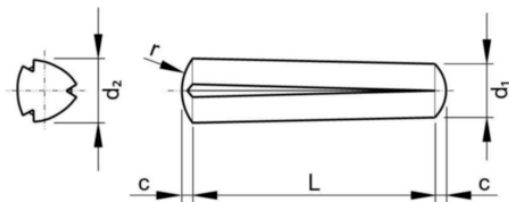

$r \approx 2.5$

Tolerance h9

V 4.25