



Grooved pin, half length taper grooved DIN 1472 Free-cutting steel 5X36MM

Article number	39720.050.036
Brand	-
UBB	500645367953
UNSPSC	31163215
EAN	8717077083882
PKG. of 100	Full Box Only

Technical Parameters

Diameter	5 mm
Length	36 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

ISO	≈8745
NEN	≈2603
DIN	1472

Technical Specification

c ≈	0.6
d1	5
d2 ≈	5.3
D (mm)	5
L (mm)	36

Technical Drawing

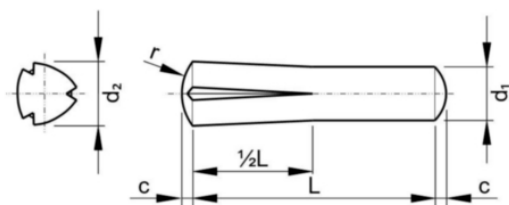

$r \approx$

5

Tolerance

h11

V

16.5