



## Grooved pin, half length reverse DIN 1474 Free-cutting steel 1,5X8MM

|                |               |
|----------------|---------------|
| Article number | 39740.015.008 |
| Brand          | -             |
| UBB            | 950359139389  |
| UNSPSC         | 31163215      |
| EAN            | 8715492826503 |
| PKG. of 200    | Full Box Only |

### Technical Parameters

|          |                                                                                                                                                                                                                                                                                                                                     |
|----------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Diameter | 1.5 mm                                                                                                                                                                                                                                                                                                                              |
| Length   | 8 mm                                                                                                                                                                                                                                                                                                                                |
| Material | Free-cutting steel                                                                                                                                                                                                                                                                                                                  |
| Info     | V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends. |


### Standards

|     |       |
|-----|-------|
| DIN | 1474  |
| NEN | ≈2605 |
| ISO | ≈8741 |

### Technical Specification

|        |     |
|--------|-----|
| c ≈    | 0.2 |
| d1     | 1.5 |
| d2 ≈   | 1.6 |
| D (mm) | 1.5 |
| L (mm) | 8   |

### Technical Drawing

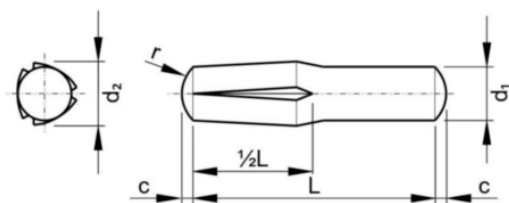

$r \approx 1.5$

Tolerance h9

$v \approx 1.6$