



Grooved pin, half length reverse DIN 1474 Free-cutting steel 2X5MM

Article number	39740.020.005
Brand	-
UBB	950359139876
UNSPSC	31163215
EAN	8715492826558
PKG. of 200	Full Box Only

Technical Parameters

Diameter	2 mm
Length	5 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

DIN	1474
ISO	≈8741
NEN	≈2605

Technical Specification

c ≈	0.25
d1	2
d2 ≈	2.15
D (mm)	2
L (mm)	5

Technical Drawing

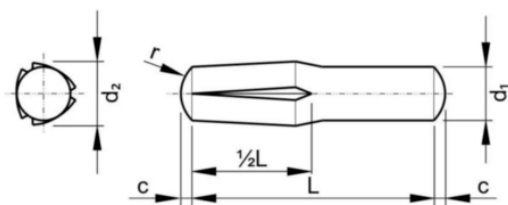

$r \approx 2$

Tolerance h9

V 2.85