



Grooved pin with round head DIN 1476 Aluminium 4X10MM

Article number	45390.040.010
Brand	-
UBB	500648885191
UNSPSC	31163215
EAN	8717077230040
PKG. of 500	Full Box Only

Technical Parameters

Diameter	4 mm
Length	10 mm
Head shape	Round head
Material	Aluminium
Info	Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The tolerance class of the nominal length (L) is js15.


Standards

DIN	1476
-----	------

Technical Specification

d1	4
d2 ≈	4.25
d3	7
D (mm)	4
f ≈	1.5
k	2.4
L (mm)	10
r ≈	3.8

Technical Drawing

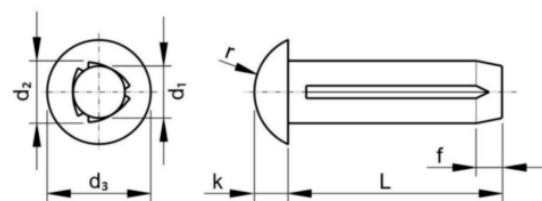

Tolerance +0/-0.1

FABORY