


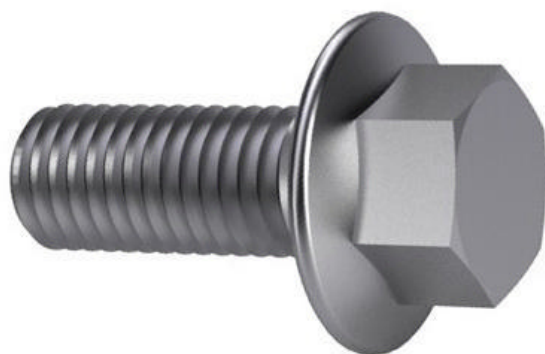

**Hexagon flange bolt,
fully threaded DIN ≈6921
Stainless steel A2 70 M5X8**

Article number	51018.050.008
Brand	-
UBB	500634387871
UNSPSC	31161620
EAN	8715494550819
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	8 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A2
Thread direction	Right
Thread	Metric thread

Standards

ASME	≈B18.2.3.4M
EN	≈1665
DIN	≈6921
ISO	≈4162

Technical Specification

b (min.)	16
d-D	M5
dc (max.)	11.8
k (max.)	5.4
L (mm)	8
P	0.8
s	8

Technical Drawing

