


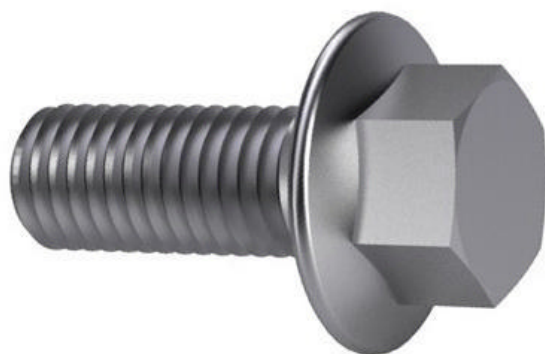

**Hexagon flange bolt,
fully threaded DIN ≈6921
Stainless steel A2 70 M5X30**

Article number	51018.050.030
Brand	-
UBB	500635892820
UNSPSC	31161620
EAN	8715494551021
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	30 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A2
Thread direction	Right
Thread	Metric thread

Standards

EN	≈1665
DIN	≈6921
ISO	≈4162
ASME	≈B18.2.3.4M

Technical Specification

b (min.)	16
d-D	M5
dc (max.)	11.8
k (max.)	5.4
L (mm)	30
P	0.8
s	8

Technical Drawing

