


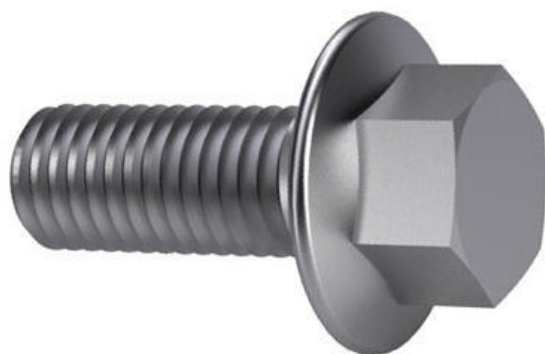

**Hexagon flange bolt,
fully threaded DIN ≈6921
Stainless steel A2 70 M5X35**

Article number	51018.050.035
Brand	-
UBB	500635892903
UNSPSC	31161620
EAN	8715494551038
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	35 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A2
Thread direction	Right
Thread	Metric thread

Standards

ISO	≈4162
ASME	≈B18.2.3.4M
EN	≈1665
DIN	≈6921

Technical Specification

b (min.)	16
d-D	M5
dc (max.)	11.8
k (max.)	5.4
L (mm)	35
P	0.8
s	8

Technical Drawing

