


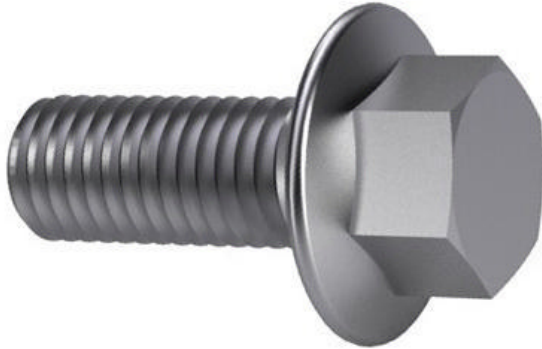

## Hexagon flange bolt, fully threaded DIN ≈6921 Stainless steel A2 70 M10X20

|                |               |
|----------------|---------------|
| Article number | 51018.100.020 |
| Brand          | -             |
| UBB            | 500635895146  |
| UNSPSC         | 31161620      |
| EAN            | 8715494552066 |
| PKG. of 100    | Full Box Only |

### Technical Parameters

|                    |                 |
|--------------------|-----------------|
| Diameter           | M10             |
| Length             | 20 mm           |
| Class              | 70              |
| Driving features   | Hexagon         |
| Head shape         | Hexagon head    |
| Material           | Stainless steel |
| Material technical | A2              |
| Thread direction   | Right           |
| Thread             | Metric thread   |

### Standards

|      |             |
|------|-------------|
| ISO  | ≈4162       |
| EN   | ≈1665       |
| ASME | ≈B18.2.3.4M |
| DIN  | ≈6921       |

### Technical Specification

|           |      |
|-----------|------|
| b (min.)  | 26   |
| d-D       | M10  |
| dc (max.) | 22.3 |
| k (max.)  | 9.2  |
| L (mm)    | 20   |
| P         | 1.5  |
| s         | 15   |

### Technical Drawing

