


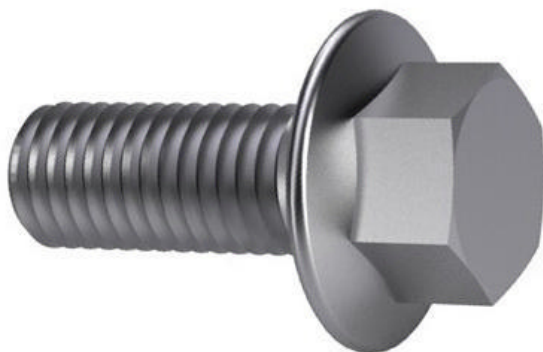

Hexagon flange bolt, fully threaded DIN ≈6921 Stainless steel A2 70

Article number	51018.120.060
Brand	-
UBB	500634389281
UNSPSC	31161620
EAN	8715494550963
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M12
Length	60 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A2
Thread direction	Right
Thread	Metric thread

Standards

ISO	≈4162
DIN	≈6921
ASME	≈B18.2.3.4M
EN	≈1665

Technical Specification

b (min.)	30
d-D	M12
dc (max.)	26.6
k (max.)	11.5
L (mm)	60
P	1.75
s	16

Technical Drawing

