


## Hexagon socket button head screw ISO 7380-1 Stainless steel A2 M8X65

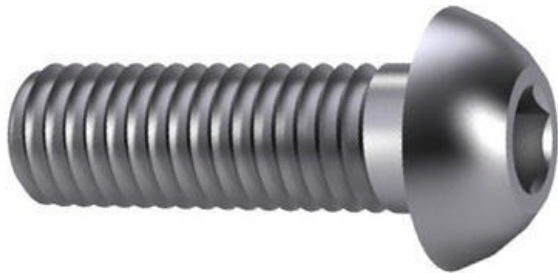

Article number	51030.080.065
Brand	-
UBB	500633135503
UNSPSC	31161518
EAN	8715494607711
PKG. of 200	Full Box Only

### Technical Parameters

Diameter (d-D)	M8
Length (L) (mm)	65
Material	Stainless steel
Head shape	Button head
Driving features	Hexagon socket
Thread direction	Right
Thread	Metric thread
Material technical	A2

### Standards

ISO	7380-1
NF	≈E25-126
BS	≈4168-6
ASME	≈B18.3.4M

**Info**

Due to the unfavourable head geometry these fasteners have reduced loadability. Steel fasteners with reduced loadability are marked with a '0' preceding the property class mark, e.g. '010.9'. Stainless steel fasteners with reduced loadability are either marked with a '0' preceding the property class mark, e.g. 'A2-070', or with the steel grade only, e.g. 'A2'.

$d_k$ (max.)	14
Full thread if $L \leq$	35
$k$ (max.)	4.4
P	1.25
s	5

**FABORY**

