


Hexagon socket head cap screw DIN 912 Stainless steel A2 70 M14X180

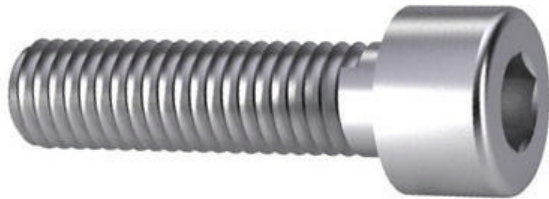

Article number	51050.140.180
Brand	-
UBB	500633164057
UNSPSC	31161605
EAN	8715494610605
PKG. of 25	Full Box Only

Technical Parameters

Diameter (d-D)	M14
Length (L) (mm)	180
Class	70
Material	Stainless steel
Head shape	Cylindrical head
Driving features	Hexagon socket
Thread direction	Right
Thread	Metric thread
Material technical	A2
Info	Sizes with a diameter M20 are minimal property class 50.

Standards

NF	E25-125
ISO	4762
DIN	912
BS	4168-1
ASME	B18.3.1M

Technical Specification

b	40
d_k (max.)	21
Full thread if $L \leq$	55
k (max.)	14
P	2
s	12

Technical Drawing

