

Self-clinching through stand off Stainless steel A1 M3X4,18X10X4

Article number	51228.030.010
Brand	-
UBB	500656769139
UNSPSC	31161816
EAN	8712423022096
PKG. of 1000	Full Box Only

Technical Parameters


Diameter	M3
Length	10 mm
Material	Stainless steel
Material technical	A1
Thread direction	Right
Thread	Metric thread
Info	Steel self-clinching through stand offs are suitable for use in steel sheet with a maximum hardness of HRB70. For steel sheets with higher hardnesses, rivet bushes are recommended.

Standards

Technical Specification

B	4
C	4.18
d-D	M3
D	3.2
Hole size	4.2
L (mm)	10

Technical Drawing

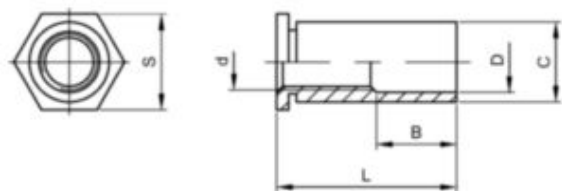

Min. distance sheet edge	6
Min. recommended sheet thickness	1
S	4.8