


## Hexalobular countersunk head screw DIN ≈965 A Stainless steel A2 M3X22

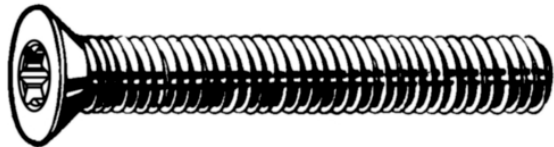

Article number	51305.030.022
Brand	-
UBB	500633226682
UNSPSC	31161504
EAN	8715494591584
PKG. of 500	Full Box Only

### Technical Parameters

Diameter (d-D)	M3
Length (L) (mm)	22
Material	Stainless steel
Head shape	Countersunk head
Driving features	Hexalobular
Thread	Metric thread
Extra info	All dimensions are guide values and may deviate dependent on the manufacturer.
Material technical	A2

### Standards

DIN	≈965 A
NF	≈E25-119-1
ISO	≈14581

### Technical Specification

Thread length (min.)	19
$d_k$ (max.)	5.6
Full thread if $L \leq$	22
$k$ (max.)	1.65
P	0.50
Socket	T10

### Technical Drawing

