


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A2 M4X45

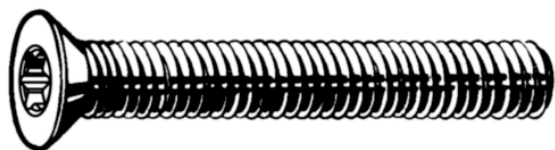

Article number	51305.040.045
Brand	-
UBB	500633227425
UNSPSC	31161504
EAN	8715494591669
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M4
Length	45 mm
Class	70
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

ISO	≈14581
NF	≈E25-119-1
DIN	≈965

Technical Specification

d-D	M4
Thread length (min.)	22
dk (max.)	7.5
Full thread if $L \leq$	25
k (max.)	2.2
L (mm)	45
P	0.7
Socket	20

Technical Drawing

