


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A2 M8X35

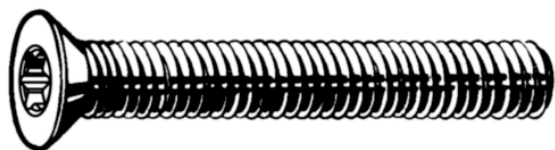

Article number	51305.080.035
Brand	-
UBB	500633230130
UNSPSC	31161504
EAN	8715494591935
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	35 mm
Class	70
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

NF	≈E25-119-1
DIN	≈965
ISO	≈14581

Technical Specification

d-D	M8
Thread length (min.)	34
dk (max.)	14.5
Full thread if $L \leq$	40
k (max.)	4
L (mm)	35
P	1.25
Socket	45

Technical Drawing

