


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A2 M8X45

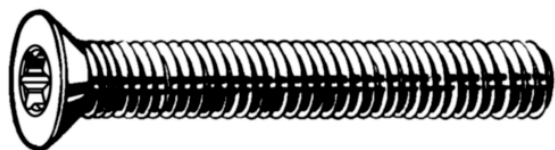

Article number	51305.080.045
Brand	-
UBB	500633230395
UNSPSC	31161504
EAN	8715494591959
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	45 mm
Class	70
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

NF	≈E25-119-1
ISO	≈14581
DIN	≈965

Technical Specification

d-D	M8
Thread length (min.)	34
dk (max.)	14.5
Full thread if $L \leq$	40
k (max.)	4
L (mm)	45
P	1.25
Socket	45

Technical Drawing

