


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A2 M8X80

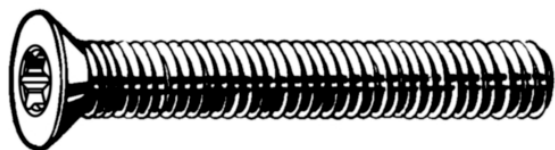

Article number	51305.080.080
Brand	-
UBB	500633230700
UNSPSC	31161504
EAN	8715494591997
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	80 mm
Class	70
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A2
Thread	Metric thread

Standards

ISO	≈14581
NF	≈E25-119-1
DIN	≈965

Technical Specification

d-D	M8
Thread length (min.)	34
dk (max.)	14.5
Full thread if $L \leq$	40
k (max.)	4
L (mm)	80
P	1.25
Socket	45

Technical Drawing

