


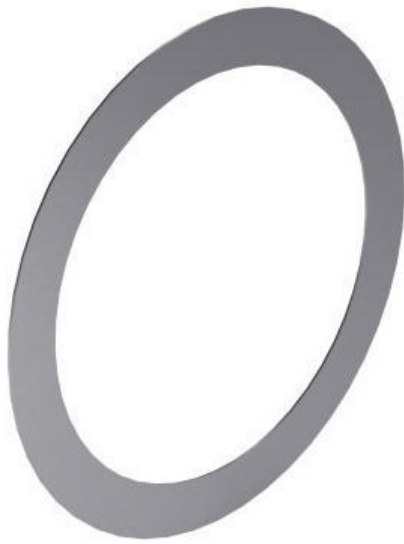

## Shim ring thickness h=0,5MM DIN 988 Stainless steel A2 h=0,5MM 5X10MM

|                |               |
|----------------|---------------|
| Article number | 51555.050.010 |
| Brand          | -             |
| UBB            | 500512306597  |
| UNSPSC         | 31163301      |
| EAN            | 8715494281706 |
| PKG. of 100    | Full Box Only |

### Technical Parameters

|                    |                 |
|--------------------|-----------------|
| Diameter           | 5 mm            |
| Material           | Stainless steel |
| Material technical | A2              |
| Outer diameter     | 10              |
| Info               | h=0,5MM         |

### Standards

|     |     |
|-----|-----|
| DIN | 988 |
|-----|-----|

### Technical Specification

|           |      |
|-----------|------|
| d1        | 5    |
| d1 (max.) | 5.15 |
| d1 (min.) | 5.03 |
| d2        | 10   |
| d2 (max.) | 9.96 |
| d2 (min.) | 9.81 |
| D (mm)    | 5    |
| Thickness | 0.5  |

### Technical Drawing

