


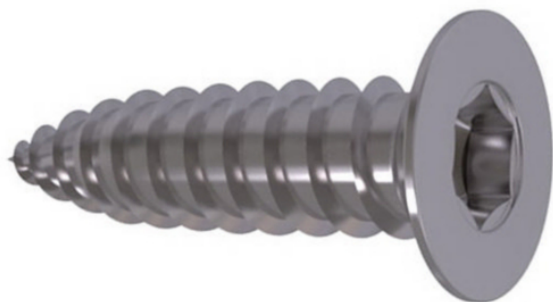

## Hexalobular socket countersunk head tapping screw ISO 14586 C Stainless steel A2 ST2,9X9,5MM

|                |               |
|----------------|---------------|
| Article number | 51683.029.009 |
| Brand          | -             |
| UBB            | 500571718401  |
| UNSPSC         | 31161507      |
| EAN            | 8715494131346 |
| PKG. of 1000   | Full Box Only |

### Technical Parameters

|                    |                     |
|--------------------|---------------------|
| Diameter           | 2.9 mm              |
| Length             | 9.5 mm              |
| Driving features   | Hexalobular         |
| Head shape         | Countersunk head    |
| Material           | Stainless steel     |
| Material technical | A2                  |
| Thread             | Self tapping thread |

### Standards

|     |         |
|-----|---------|
| ISO | 14586 C |
|-----|---------|

### Technical Specification

|           |     |
|-----------|-----|
| D (mm)    | 2.9 |
| dk (max.) | 5.5 |
| k (max.)  | 1.7 |
| L (mm)    | 9.5 |
| P         | 1.1 |
| Socket    | 10  |

### Technical Drawing

