


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A4 80 M3X8

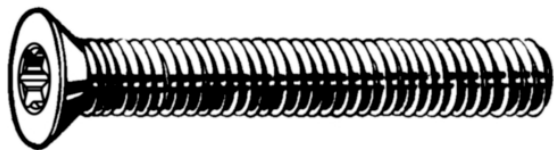

Article number	53345.030.008
Brand	-
UBB	500690308514
UNSPSC	31161504
EAN	8717077788862
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	M3
Length	8 mm
Class	80
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

ISO	14581
NF	≈E25-119-1
DIN	≈965

Technical Specification

d-D	M3
Thread length (min.)	19
dk (max.)	5.6
Full thread if L ≤	22
k (max.)	1.65
L (mm)	8
P	0.5
Socket	10

Technical Drawing

