


Hexalobular countersunk
head screw DIN ≈965 A
Stainless steel A4 80 M3X16

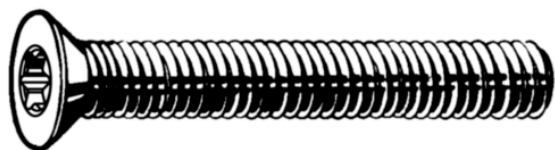

Article number	53345.030.016
Brand	-
UBB	500690308852
UNSPSC	31161504
EAN	8717077788893
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	M3
Length	16 mm
Class	80
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

DIN	≈965
NF	≈E25-119-1
ISO	14581

Technical Specification

d-D	M3
Thread length (min.)	19
dk (max.)	5.6
Full thread if $L \leq$	22
k (max.)	1.65
L (mm)	16
P	0.5
Socket	10

Technical Drawing

