


Hexalobular countersunk head screw DIN ≈965 A Stainless steel A4 80 M4X6

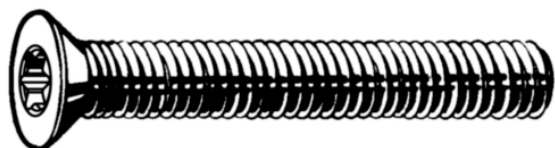

Article number	53345.040.006
Brand	-
UBB	500690309017
UNSPSC	31161504
EAN	8717077788916
PKG. of 1000	Full Box Only

Technical Parameters

Diameter (d-D)	M4
Length (L) (mm)	6
Class	80
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

NF	≈E25-119-1
DIN	≈965 A
ISO	≈14581

Technical Specification

Thread length (min.)	22
d_k (max.)	7.5
Full thread if $L \leq$	25
k (max.)	2.2
P	0.70
Socket	T20

Technical Drawing

