


Hexalobular countersunk head screw DIN ≈965 A Stainless steel A4 80 M4X8

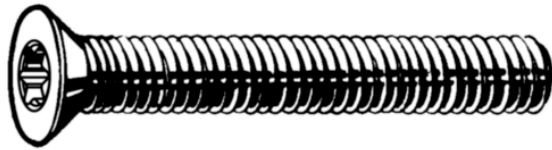

Article number	53345.040.008
Brand	-
UBB	500690309199
UNSPSC	31161504
EAN	8717077788923
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	M4
Length	8 mm
Class	80
Driving features	Hexalobular
Head shape	Countersunk head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

DIN	≈965
NF	≈E25-119-1
ISO	14581

Technical Specification

d-D	M4
Thread length (min.)	22
dk (max.)	7.5
Full thread if $L \leq$	25
k (max.)	2.2
L (mm)	8
P	0.7
Socket	20

Technical Drawing

