


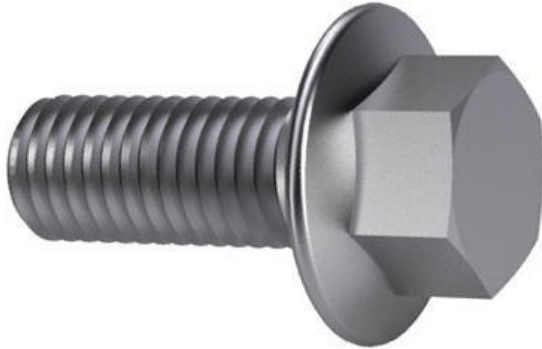

Hexagon flange bolt, fully threaded DIN ≈6921 Stainless steel A4 70 M10X35

Article number	55018.100.035
Brand	-
UBB	500634447774
UNSPSC	31161620
EAN	8715494554749
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Length	35 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

ASME	≈B18.2.3.4M
DIN	≈6921
ISO	≈4162
EN	≈1665

Technical Specification

b (min.)	26
d-D	M10
dc (max.)	22.3
k (max.)	9.2
L (mm)	35
P	1.5
s	15

Technical Drawing

