


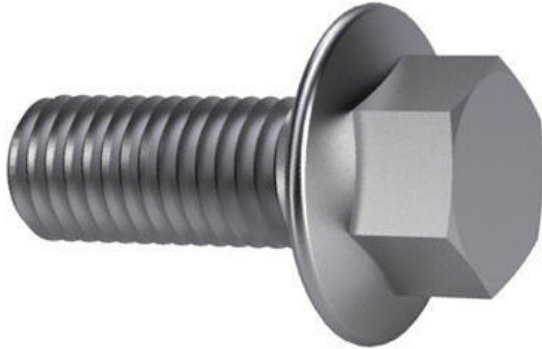

Hexagon flange bolt, fully threaded DIN ≈6921 Stainless steel A4 70 M10X65

Article number	55018.100.065
Brand	-
UBB	500634448350
UNSPSC	31161620
EAN	8715494554961
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Length	65 mm
Class	70
Driving features	Hexagon
Head shape	Hexagon head
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

EN	≈1665
ISO	≈4162
ASME	≈B18.2.3.4M
DIN	≈6921

Technical Specification

b (min.)	26
d-D	M10
dc (max.)	22.3
k (max.)	9.2
L (mm)	65
P	1.5
s	15

Technical Drawing

