


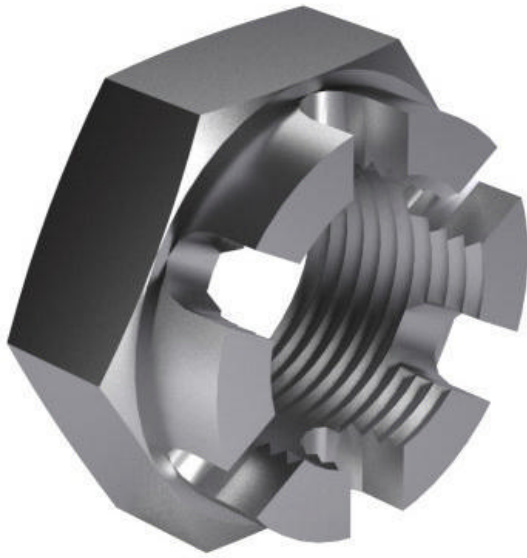

## Hexagon thin slotted and castle nut (old type) DIN 937 Stainless steel A4 035 M16

|                |               |
|----------------|---------------|
| Article number | 55225.160.001 |
| Brand          | -             |
| UBB            | 500634461866  |
| UNSPSC         | 31161707      |
| EAN            | 8715494558662 |
| PKG. of 50     | Full Box Only |

### Technical Parameters

|                    |                 |
|--------------------|-----------------|
| Diameter           | M16             |
| Class              | 035             |
| Driving features   | Hexagon         |
| Material           | Stainless steel |
| Material technical | A4              |
| Thread direction   | Right           |
| Thread             | Metric thread   |

### Standards

|     |     |
|-----|-----|
| DIN | 937 |
|-----|-----|

### Technical Specification

|                  |     |
|------------------|-----|
| d-D              | M16 |
| m                | 12  |
| n                | 4.5 |
| P                | 2   |
| s                | 24  |
| Split pin DIN 94 | 4   |

### Technical Drawing

