


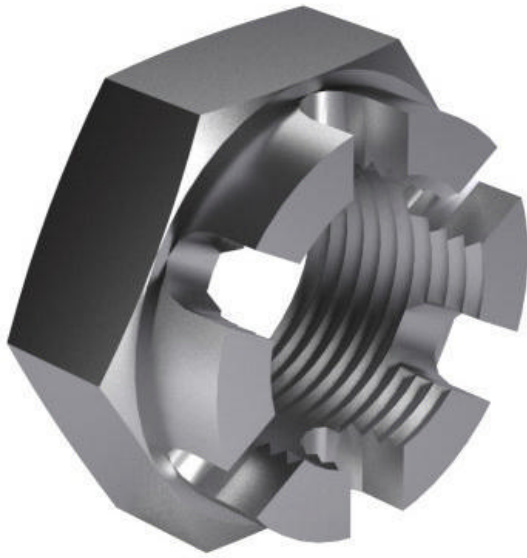

Hexagon thin slotted and castle nut (old type) DIN 937 Stainless steel A4 035 M18

Article number	55225.180.001
Brand	-
UBB	500634461940
UNSPSC	31161707
EAN	8715494558693
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M18
Class	035
Driving features	Hexagon
Material	Stainless steel
Material technical	A4
Thread direction	Right
Thread	Metric thread

Standards

DIN	937
-----	-----

Technical Specification

d-D	M18
m	13
n	4.5
P	2.5
s	27
Split pin DIN 94	4

Technical Drawing

