


Hexalobular countersunk head screw DIN ≈965 A Stainless steel A4 M8X70

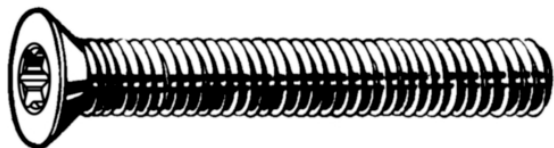

Article number	55303.080.070
Brand	-
UBB	500633414296
UNSPSC	31161504
EAN	8715494624220
PKG. of 200	Full Box Only

Technical Parameters

Diameter (d-D)	M8
Length (L) (mm)	70
Material	Stainless steel
Head shape	Countersunk head
Driving features	Hexalobular
Thread	Metric thread
Extra info	All dimensions are guide values and may deviate dependent on the manufacturer.
Material technical	A4

Standards

NF	≈E25-119-1
DIN	≈965 A
ISO	≈14581

Technical Specification

Thread length (min.)	34
d_k (max.)	14.5
Full thread if $L \leq$	40
k (max.)	4
P	1.25
Socket	T45

Technical Drawing

