



Steel Plain 40X70X65MM

Article number	57807.470.065
Brand	-
UBB	950185032501
UNSPSC	26101765
EAN	8715492878922
PKG. of 1	Full Box Only

Technical Parameters

Diameter	40 mm
Length	65 mm
Material	Steel
Surface treatment	Plain
Type no.	VP

Info


The cylindrical bush type VP is designed to accommodate torsional movements and axial and radial loads. It consists of two concentric sleeves with rubber, 60° IRH, securely bonded between them.

Standards

Technical Specification

d1	40
d2	70
D (mm)	40
Fa (max.) (N)	8300
Fr (max.) (N)	20500
i	55
L (mm)	65

Technical Drawing

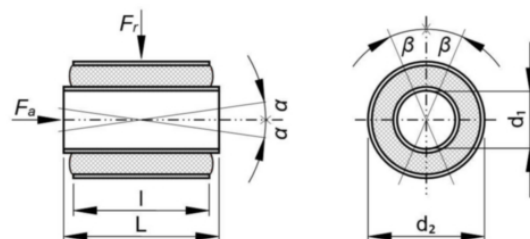

α (max.) ino 7

β (max.) ino 12