



## Spring plungers with slot and thrust pin, LONG-LOK secured standard spring force Stainless steel 1.4305 M12

Article number	58535.120.001
Brand	-
UBB	500689838521
UNSPSC	31162807
EAN	
PKG. of 5	Full Box Only

### Technical Parameters


D1_MM	6mm
Driving features	Slotted
Material	Stainless steel
Material technical	1.4305
Thread	Metric thread
Info	Material: Sleeve 1.4305. Thrust pin 1.4034. Spring 1.4310. LONG-LOK thread lock in nylon.Version: Bright. Thrust pin hardened. L2 = approx. 2x thread pitch.

### Standards

### Technical Specification

D	12
D1	6
F1 = springiness beginning in N	30
F2 = springiness end in N	55
H	3.5
L1	10

### Technical Drawing

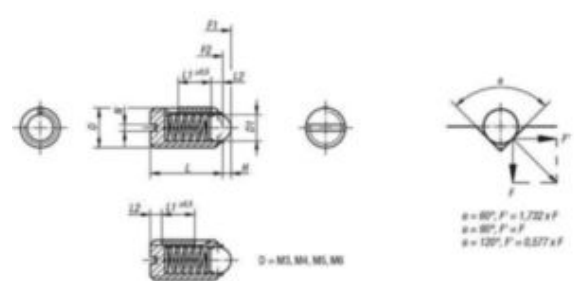

Loosening torque approx. (Nm)	1.41
N	2
L	22
Tightening torque approx. (Nm)	2.11