


FISCHER Wall plug type S Plastic Nylon (polyamide) large pack S 6

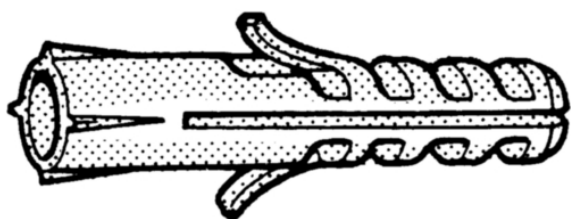

Article No.	63110.060.001
Brand	-
UBB	950372002010
UNSPSC	31162103
EAN	4006209501221
PKG. of 500	Full Box Only

Technical Parameters


Diameter (mm)	6
Type	S 6
Info	Allowable load in kN at the largest possible screw diameter, (values in bold print), and a correct mounting of the wall plug in a supporting surface. Allowable load includes the safety factor 7.
Color	Grey
Extra info	large pack
Material	Plastic
Material technical	Nylon (polyamide)
Type no.	S

Standards

Technical Specification

Brick \geq Mz12	0.28
Cellular concrete \geq PB4, PP4 (G4)	0.05
Concrete \geq C20/25	0.40
Diameter (mm)	6
Drill depth (min.)	40
Drill \varnothing	6

Technical Drawing

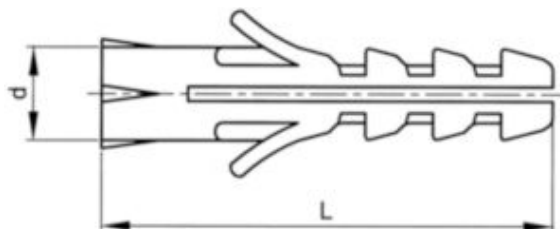

Length (L) (mm)	30
Sandlime brick \geq	0.28
KS12 <i>OF COURSE.</i> <small>SETTING THE STANDARD</small>	
Wood or chipboard screws	4-5