


## FISCHER Universal fixing Plastic Nylon (polyamide) FU 8X50

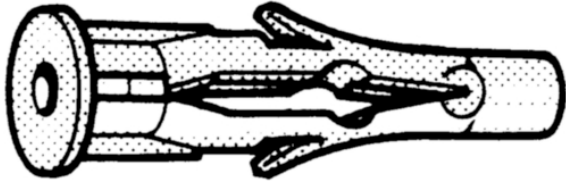

|                |               |
|----------------|---------------|
| Article number | 63270.080.050 |
| Brand          | -             |
| UBB            | 950372028684  |
| UNSPSC         | 31162103      |
| EAN            | 4006209532645 |
| PKG. of 50     | Full Box Only |

### Technical Parameters

|          |         |
|----------|---------|
| Diameter | 8 mm    |
| Length   | 50 mm   |
| Color    | Grey    |
| Material | Plastic |
| Type no. | FU      |


**Info** Allowable load in kN at the largest possible screw diameter, (values in bold print), and a correct mounting of the wall plug in a supporting surface. Allowable load includes the safety factor 7.

### Standards

### Technical Specification

|                                 |      |
|---------------------------------|------|
| Brick Mz12                      | 0.5  |
| Cellular concrete PB2, PP2 (G2) | 0.09 |
| Cellular concrete PB4, PP4 (G4) | 0.22 |
| Concrete C20/25                 | 0.57 |
| D (mm)                          | 8    |
| Drill depth (min.)              | 60   |
| Drill ø                         | 8    |

### Technical Drawing

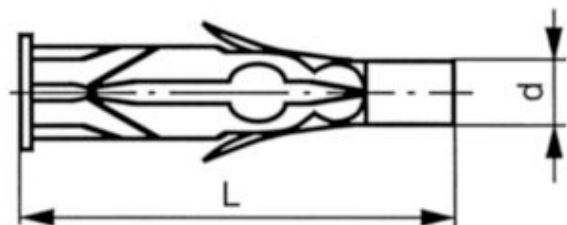

|                           |         |
|---------------------------|---------|
| L (mm)                    | 50      |
| Material thickness (min.) | 6       |
| Pumice grit V2            | 0.21    |
| Sandlime brick KS12       | 0.5     |
| Type                      | FU 8X50 |
| Wood or chipboard screws  | 4.5     |