



FISCHER Turbo anchor FTP steel Steel Plain M6

Article number	63309.060.001
Brand	-
UBB	500501457914
UNSPSC	31162103
EAN	4006209784150
PKG. of 25	Full Box Only

Technical Parameters


Diameter	M6
Material	Steel
Surface treatment	Plain
Type no.	FTP
Info	Tools, see following pages. Allowable loads in kN are valid for screws with specified diameters. Allowable load includes the safety factor 5. Drill $\varnothing$ values between brackets applied to cellular concrete class $\geq 5,0$ N/mm ² .

Standards

Technical Specification

Cellular concrete PB2, PP2 ($\geq 2,5$ N/mm ²)	0.3
Cellular concrete PB4, PP4 ($\geq 5,0$ N/mm ²)	0.5
Cellular concrete PB6, PP6 ($\geq 7,5$ N/mm ²)	0.7
d-D	M6
Depth of drilled hole to deepest point	60

Technical Drawing

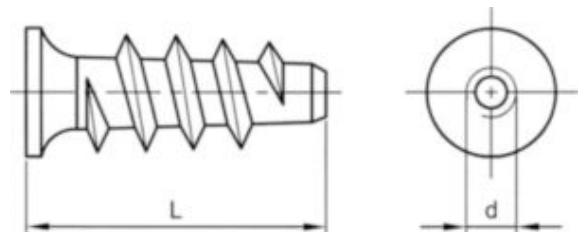

Drill ø	8
L (mm)	50
Screw ø	M6
Screw-in depth (max.)	20