


FISCHER Anchor Brass PA4 M6X7,5

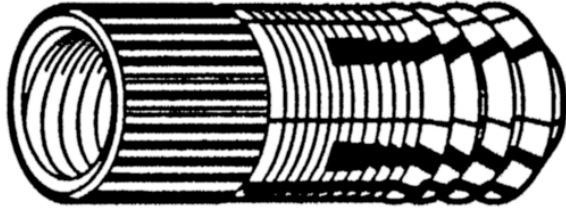

Article number	63410.060.007
Brand	-
UBB	950372021572
UNSPSC	31162101
EAN	4006209504840
PKG. of 200	Full Box Only

Technical Parameters


Key features	0.75
Material	Brass
Thread	Metric thread
Type no.	PA 4
Info	Length of screw min. = length of plug + thickness of fixing part. Allowable load (kN) for a single anchor, valid for machine screws with the specified thread size. Allowable load includes the safety factor 4.

Standards

Technical Specification

Assembly depth (min.)	7.5
Beech wood	0.5
Chipboard	0.2
d-D	M6
Drill depth (min.)	7.5
Drill ø	8
Drill ø in construction	7.5
L (mm)	7.5
P	1
Pine wood	0.18

Technical Drawing

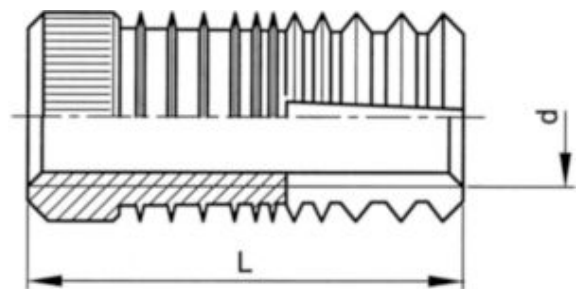

Plastic	0.75
---------	------

Type	PA4 M6X7,5
------	------------

FABORY