


FISCHER Anchor Brass PA4 M10X25

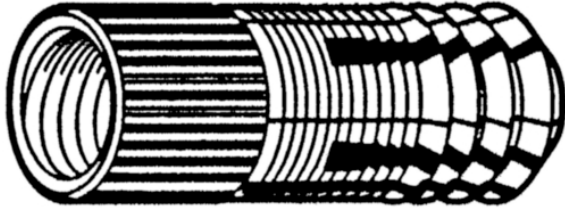

Article number	63410.100.025
Brand	-
UBB	950372021994
UNSPSC	31162101
EAN	4006209504864
PKG. of 25	Full Box Only

Technical Parameters

Material	Brass
Thread	Metric thread
Type no.	PA 4
Info	Length of screw min. = length of plug + thickness of fixing part. Allowable load (kN) for a single anchor, valid for machine screws with the specified thread size. Allowable load includes the safety factor 4.

Standards

Technical Specification

Assembly depth (min.)	25
Brick Mz12	2.3
d-D	M10
Drill depth (min.)	25
Drill ø	12
Drill ø in construction	11.5
L (mm)	25
P	1.5
Type	PA4 M10X25

Technical Drawing

