



SPIT Female threaded hammer-in anchor SA Stainless steel A4 M6

Article number	70875.060.001
Brand	-
UBB	950352934224
UNSPSC	31162101
EAN	8715492906175
PKG. of 100	Full Box Only

Technical Parameters


Diameter	M6
Material	Stainless steel
Thread	Metric thread
Type no.	SA
Info	Female threaded hammer-in anchor type GRIP SA can be installed with setting tool type S (see article group 70967). Allowable design load $N_{rd,c}$ (kN) for a single anchor in concrete C20/25 without influence of edge distances or other anchors. Allowable load includes the safety factor $\gamma_m = 1,5$, see approval.

Standards

Technical Specification

a	13
Concrete $\geq$ C20/25	5.5
d-D	M6
d2	8
Drill depth (min.)	32

Technical Drawing

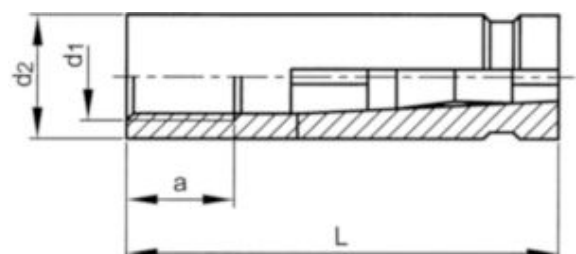

Drill ø 8

L (mm) 30

Tightening torque
(Nm) 5