


SECURITY Kinmar® permanent sleeve anchor Steel Zinc plated M8X50

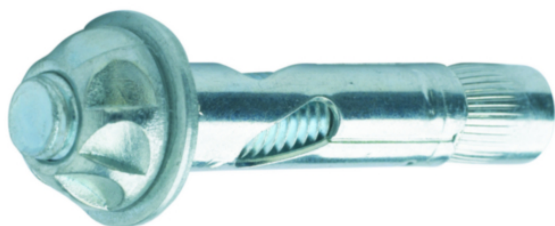

Article number	70932.080.050
Brand	-
UBB	500662899631
UNSPSC	31162101
EAN	8712423045798
PKG. of 50	Full Box Only

Technical Parameters


Diameter (d-D)	M8
Length (L) (mm)	50
Info	d2 = Nominal diameter of drill bit. tfix = Grip range. Min. td = Recommended drilling depth. These anchors are not intended for heavy duty structural applications. Tooling available on request.
Driving features	Kinmar® permanent
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

Technical Specification

Allowable static tension load (kN)	1.9
Allowable static shear load (kN)	6.5
d ₁ (max.)	16.15
d ₂	10
Drive size	KM08P

Technical Drawing

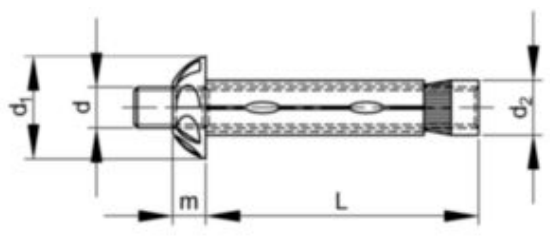

m (max.) 7.39

Min. t_d 45

t_{fix} (max.) 6

SETTING STANDARD
FASTENING SOLUTIONS