

SECURITY Kinmar® permanent sleeve anchor Steel Zinc plated M8X70

Article number	70932.080.070
Brand	-
UBB	500662899896
UNSPSC	31162101
EAN	8712423045811
PKG. of 50	Full Box Only

Technical Parameters


Length	70 mm
Driving features	Kinmar® permanent
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	d2 = Nominal diameter of drill bit. tfix = Grip range.Min. td = Recommended drilling depth.These anchors are not intended for heavy duty structural applications.Tooling available on request.

Standards

Technical Specification

Allowable static tension load (kN)	1.9
Allowable static shear load (kN)	6.5
d-D	M8
d1 (max.)	16.15
d2	10
L (mm)	70

Technical Drawing

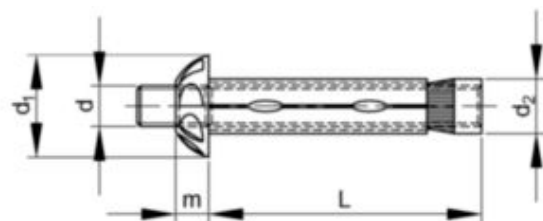

m (max.) 7.39

Min. to 45

tfix(max.) 25

FABORY