

SECURITY Kinmar® permanent sleeve anchor Steel Zinc plated M8X90

Article number	70932.080.090
Brand	-
UBB	500662899979
UNSPSC	31162101
EAN	8712423045828
PKG. of 50	Full Box Only

Technical Parameters


Length	90 mm
Driving features	Kinmar® permanent
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	d2 = Nominal diameter of drill bit. tfix = Grip range. Min. td = Recommended drilling depth. These anchors are not intended for heavy duty structural applications. Tooling available on request.

Standards

Technical Specification

Allowable static tension load (kN)	1.9
Allowable static shear load (kN)	6.5
d-D	M8
d1 (max.)	16.15
d2	10
L (mm)	90

Technical Drawing

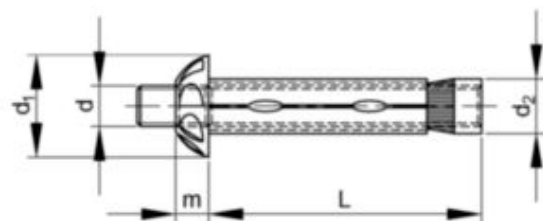

m (max.)	7.39
----------	------

Min. to	45
---------	----

tfix(max.)	45
------------	----

FABORY