


Self-cutting threaded insert type 302 Stainless steel A1 M3X6

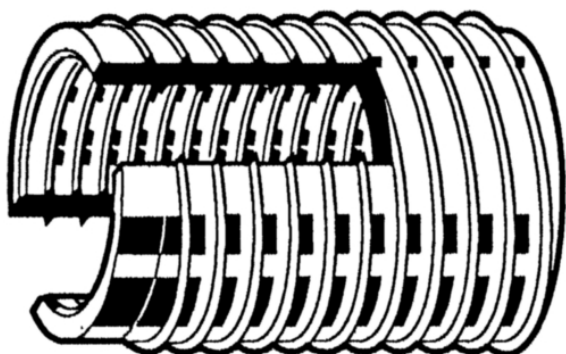

Article No.	71566.030.001
Brand	-
UBB	950355789054
UNSPSC	31162802
EAN	8715492910271
PKG. of 25	Full Box Only

Technical Parameters

d_1	M3
Length (L) (mm)	6
Info	Drill depth (min.) = Minimum borehole depth for blind holes.
Diameter (d-D)	M3
Material	Stainless steel
Material technical	A1
Thread	Metric thread
Type no.	302
Info	Type 302 inserts may be used in materials with a tensile strength up to 320 MPa.

Standards

Technical Specification

d_2	5
Drill depth (min.)	8
P (d_1)	0.50
P (d_2)	0.50

Technical Drawing

