


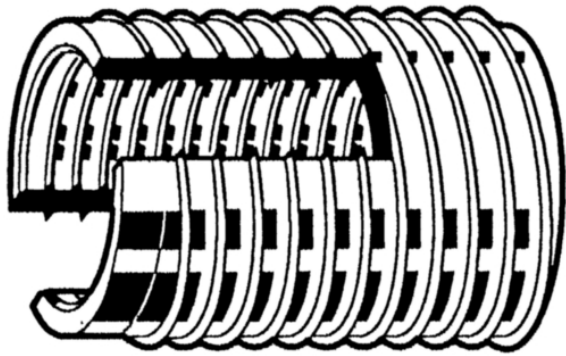

Self-cutting threaded insert type 302 Stainless steel 1.4305 M10X18

Article number	71566.100.001
Brand	-
UBB	950355789542
UNSPSC	31162802
EAN	8715492910325
PKG. of 10	Full Box Only

Technical Parameters

Diameter	M10
Length	18 mm
Material	Stainless steel
Material technical	A1
Thread	Metric thread
Type no.	302
Info	Type 302 inserts may be used in materials with a tensile strength up to 320 MPa. Drill depth (min.) = Minimum borehole depth for blind holes.

Standards

Technical Specification

d-D	M10
d1	M10
d2	14
Drill depth (min.)	22
L (mm)	18
P (d1)	1.5
P (d2)	1.5

Technical Drawing

