


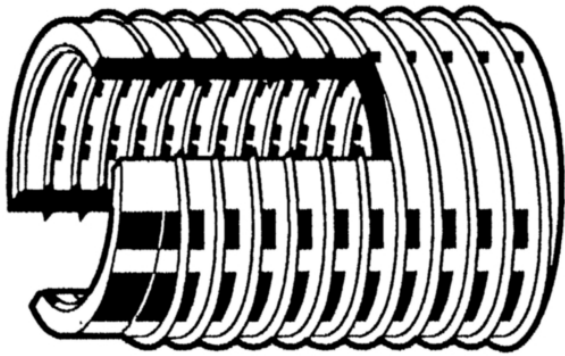

Self-cutting threaded insert type 302 Steel Case-hardened Zinc plated M6X14

Article number	71571.060.001
Brand	-
UBB	500682478457
UNSPSC	31162802
EAN	8717077782884
PKG. of 50	Full Box Only

Technical Parameters

Length	14 mm
Material	Steel
Material technical	Case-hardened
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	302
Info	Drill depth (min.) = Minimum borehole depth for blind holes.

Standards

Technical Specification

d1	M6
d2	10
Drill depth (min.)	17
L (mm)	14
P (d1)	1
P (d2)	1.5

Technical Drawing

