


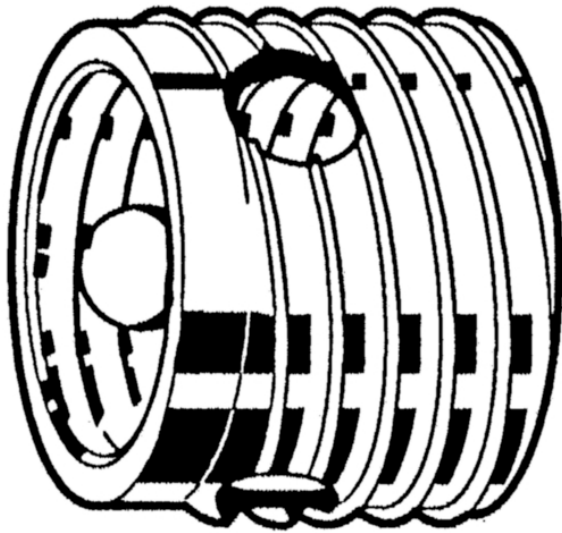

Self-cutting threaded insert type 307/308 Steel Zinc plated 307 M6X8

Article number	71752.060.008
Brand	-
UBB	500693875253
UNSPSC	31162802
EAN	8717077789678
PKG. of 1	Full Box Only

Technical Parameters

Length	8 mm
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	307
Info	Drill depth (min.) = Minimum borehole depth for blind holes.307

Standards

Technical Specification

d1	M6
d2	10
Drill depth (min.)	10
L (mm)	8
P (d1)	1
P (d2)	1.25

Technical Drawing

