


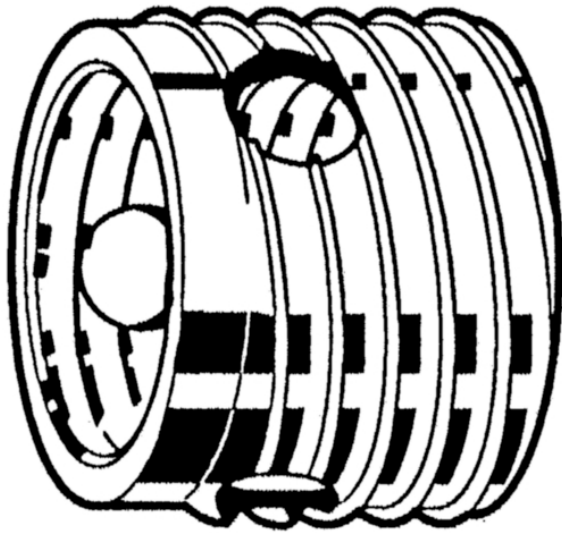

Self-cutting threaded insert type 307/308 Steel Zinc plated 307 M10X10

Article number	71752.100.010
Brand	-
UBB	500693875410
UNSPSC	31162802
EAN	8717077789692
PKG. of 1	Full Box Only

Technical Parameters

Length	10 mm
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	307
Info	Drill depth (min.) = Minimum borehole depth for blind holes.307

Standards

Technical Specification

d1	M10
d2	14
Drill depth (min.)	13
L (mm)	10
P (d1)	1.5
P (d2)	1.5

Technical Drawing

