


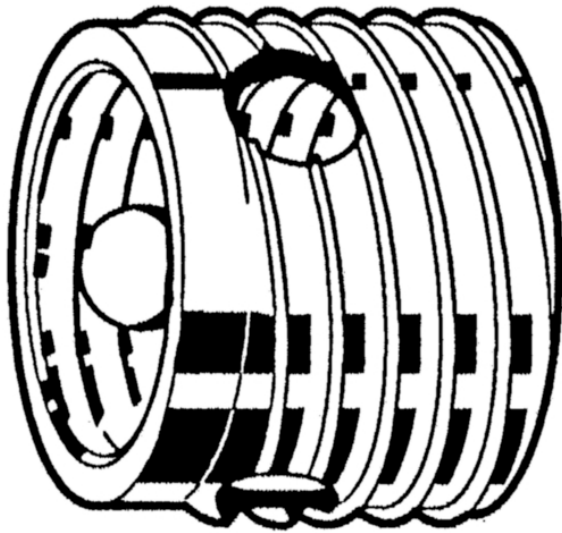

Self-cutting threaded insert type 307/308 Steel Zinc plated 307 M12X12

Article number	71752.120.012
Brand	-
UBB	500693875584
UNSPSC	31162802
EAN	8717077789708
PKG. of 1	Full Box Only

Technical Parameters

Length	12 mm
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	307
Info	Drill depth (min.) = Minimum borehole depth for blind holes.307

Standards

Technical Specification

d1	M12
d2	16
Drill depth (min.)	15
L (mm)	12
P (d1)	1.75
P (d2)	1.75

Technical Drawing

