


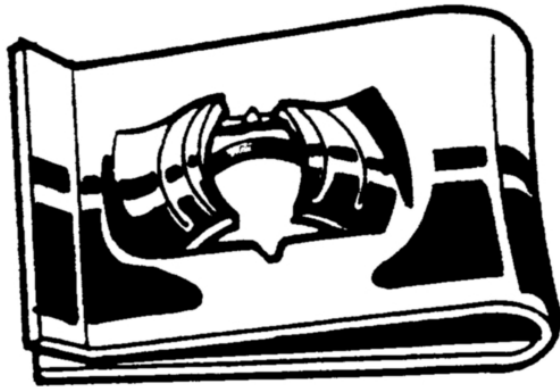

Speednut type SNU Spring steel Zinc plated ST5,5 (SNU 0538)

Article number	72294.055.001
Brand	-
UBB	500711720713
UNSPSC	31161725
EAN	8715494006323
PKG. of 50	Full Box Only

Technical Parameters

Diameter	5.5 mm
Material	Spring steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Self tapping thread

Standards

Technical Specification

a	26.2
b	15.1
c	11.1
D (mm)	5.5
For screw	ST5.5
m	10
s	0.8
t	0.9
Type	SNU

Technical Drawing

